

TAPE AND REEL INFORMATION



*All dimensions are nominal

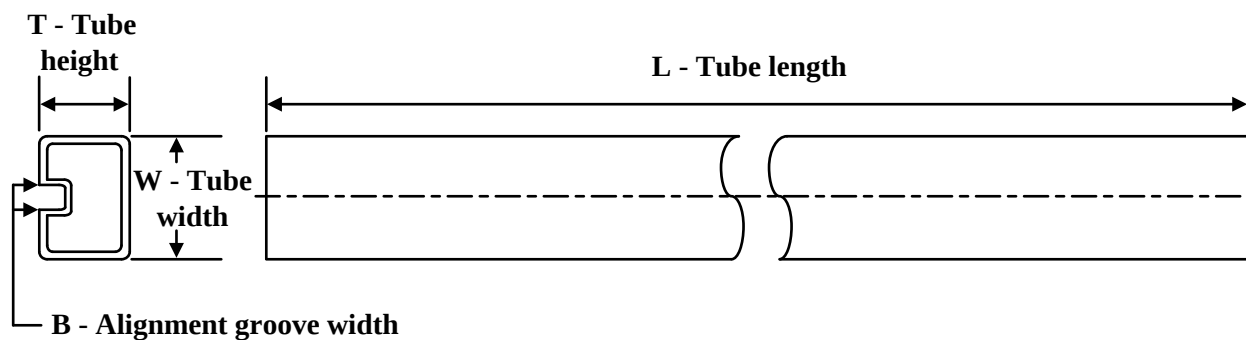
Device	Package Type	Package Drawing	Pins	SPQ	Reel Diameter (mm)	Reel Width W1 (mm)	A0 (mm)	B0 (mm)	K0 (mm)	P1 (mm)	W (mm)	Pin1 Quadrant
DAC8168IAPWR	TSSOP	PW	14	2000	330.0	12.4	6.9	5.6	1.6	8.0	12.0	Q1
DAC8168ICPWR	TSSOP	PW	16	2000	330.0	12.4	6.9	5.6	1.6	8.0	12.0	Q1

TAPE AND REEL BOX DIMENSIONS



*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Length (mm)	Width (mm)	Height (mm)
DAC8168IAPWR	TSSOP	PW	14	2000	350.0	350.0	43.0
DAC8168ICPWR	TSSOP	PW	16	2000	350.0	350.0	43.0

TUBE


*All dimensions are nominal

Device	Package Name	Package Type	Pins	SPQ	L (mm)	W (mm)	T (μm)	B (mm)
DAC7568IPW	PW	TSSOP	14	90	530	10.2	3600	3.5
DAC7568IPW.A	PW	TSSOP	14	90	530	10.2	3600	3.5
DAC7568IPWG4	PW	TSSOP	14	90	530	10.2	3600	3.5
DAC7568IPWG4.A	PW	TSSOP	14	90	530	10.2	3600	3.5
DAC7568ICPW	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC7568ICPW	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC7568ICPW.A	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC7568ICPW.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC7568ICPWG4	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC7568ICPWG4.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8168IPW	PW	TSSOP	14	90	530	10.2	3600	3.5
DAC8168IPW.A	PW	TSSOP	14	90	530	10.2	3600	3.5
DAC8168ICPW	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8168ICPW.A	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IPW	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IPW	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IPW.A	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IPW.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IPWG4	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IPWG4.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IBPW	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IBPW	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IBPW.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IBPW.A	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IBPWG4	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IBPWG4.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568ICPW	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568ICPW	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568ICPW.A	PW	TSSOP	16	90	508	8.5	3250	2.8

Device	Package Name	Package Type	Pins	SPQ	L (mm)	W (mm)	T (μm)	B (mm)
DAC8568ICPW.A	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568ICPWG4	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568ICPWG4.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IDPW	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IDPW	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IDPW.A	PW	TSSOP	16	90	530	10.2	3600	3.5
DAC8568IDPW.A	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IDPWG4	PW	TSSOP	16	90	508	8.5	3250	2.8
DAC8568IDPWG4.A	PW	TSSOP	16	90	508	8.5	3250	2.8