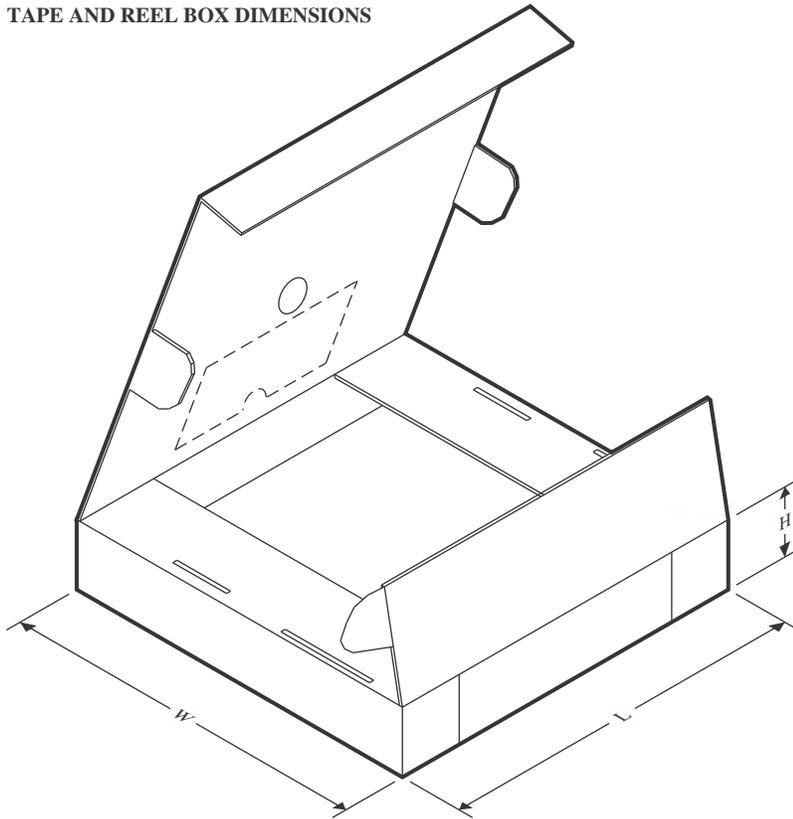


**TAPE AND REEL INFORMATION**

**QUADRANT ASSIGNMENTS FOR PIN 1 ORIENTATION IN TAPE**


\*All dimensions are nominal

| Device       | Package Type | Package Drawing | Pins | SPQ  | Reel Diameter (mm) | Reel Width W1 (mm) | A0 (mm) | B0 (mm) | K0 (mm) | P1 (mm) | W (mm) | Pin1 Quadrant |
|--------------|--------------|-----------------|------|------|--------------------|--------------------|---------|---------|---------|---------|--------|---------------|
| INA133U/2K5  | SOIC         | D               | 8    | 2500 | 330.0              | 12.4               | 6.4     | 5.2     | 2.1     | 8.0     | 12.0   | Q1            |
| INA133UA/2K5 | SOIC         | D               | 8    | 2500 | 330.0              | 12.4               | 6.4     | 5.2     | 2.1     | 8.0     | 12.0   | Q1            |

**TAPE AND REEL BOX DIMENSIONS**


\*All dimensions are nominal

| Device       | Package Type | Package Drawing | Pins | SPQ  | Length (mm) | Width (mm) | Height (mm) |
|--------------|--------------|-----------------|------|------|-------------|------------|-------------|
| INA133U/2K5  | SOIC         | D               | 8    | 2500 | 353.0       | 353.0      | 32.0        |
| INA133UA/2K5 | SOIC         | D               | 8    | 2500 | 353.0       | 353.0      | 32.0        |

**TUBE**


\*All dimensions are nominal

| Device      | Package Name | Package Type | Pins | SPQ | L (mm) | W (mm) | T (μm) | B (mm) |
|-------------|--------------|--------------|------|-----|--------|--------|--------|--------|
| INA133U     | D            | SOIC         | 8    | 75  | 506.6  | 8      | 3940   | 4.32   |
| INA133UA    | D            | SOIC         | 8    | 75  | 506.6  | 8      | 3940   | 4.32   |
| INA2133U    | D            | SOIC         | 14   | 50  | 506.6  | 8      | 3940   | 4.32   |
| INA2133U.A  | D            | SOIC         | 14   | 50  | 506.6  | 8      | 3940   | 4.32   |
| INA2133UA   | D            | SOIC         | 14   | 50  | 506.6  | 8      | 3940   | 4.32   |
| INA2133UA.A | D            | SOIC         | 14   | 50  | 506.6  | 8      | 3940   | 4.32   |