


TAPE AND REEL INFORMATION



*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Reel Diameter (mm)	Reel Width W1 (mm)	A0 (mm)	B0 (mm)	K0 (mm)	P1 (mm)	W (mm)	Pin1 Quadrant
SN65C1167ENSR	SOP	NS	16	2000	330.0	16.4	8.1	10.4	2.5	12.0	16.0	Q1
SN65C1167ENSRG4	SOP	NS	16	2000	330.0	16.4	8.1	10.4	2.5	12.0	16.0	Q1
SN65C1167EPWR	TSSOP	PW	16	2000	330.0	12.4	6.9	5.6	1.6	8.0	12.0	Q1
SN65C1167EPWRG4	TSSOP	PW	16	2000	330.0	12.4	6.9	5.6	1.6	8.0	12.0	Q1
SN65C1167ERGYR	VQFN	RGY	16	3000	330.0	12.4	3.8	4.3	1.5	8.0	12.0	Q1
SN65C1167ERGYRG4	VQFN	RGY	16	3000	330.0	12.4	3.8	4.3	1.5	8.0	12.0	Q1
SN65C1168ENSR	SOP	NS	16	2000	330.0	16.4	8.1	10.4	2.5	12.0	16.0	Q1
SN65C1168EPWR	TSSOP	PW	16	2000	330.0	12.4	6.9	5.6	1.6	8.0	12.0	Q1
SN65C1168ERGYR	VQFN	RGY	16	3000	330.0	12.4	3.8	4.3	1.5	8.0	12.0	Q1
SN65C1168ERGYRG4	VQFN	RGY	16	3000	330.0	12.4	3.8	4.3	1.5	8.0	12.0	Q1

TAPE AND REEL BOX DIMENSIONS

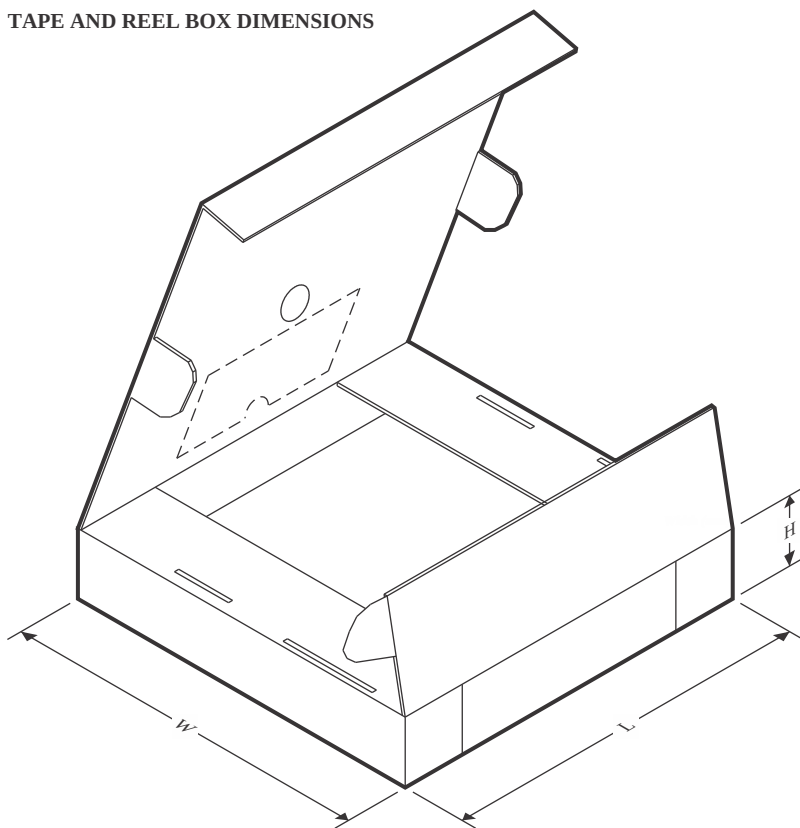

*All dimensions are nominal

Device	Package Type	Package Drawing	Pins	SPQ	Length (mm)	Width (mm)	Height (mm)
SN65C1167ENSR	SOP	NS	16	2000	353.0	353.0	32.0
SN65C1167ENSRG4	SOP	NS	16	2000	353.0	353.0	32.0
SN65C1167EPWR	TSSOP	PW	16	2000	353.0	353.0	32.0
SN65C1167EPWRG4	TSSOP	PW	16	2000	353.0	353.0	32.0
SN65C1167ERGYR	VQFN	RGY	16	3000	360.0	360.0	36.0
SN65C1167ERGYRG4	VQFN	RGY	16	3000	360.0	360.0	36.0
SN65C1168ENSR	SOP	NS	16	2000	353.0	353.0	32.0
SN65C1168EPWR	TSSOP	PW	16	2000	353.0	353.0	32.0
SN65C1168ERGYR	VQFN	RGY	16	3000	360.0	360.0	36.0
SN65C1168ERGYRG4	VQFN	RGY	16	3000	360.0	360.0	36.0