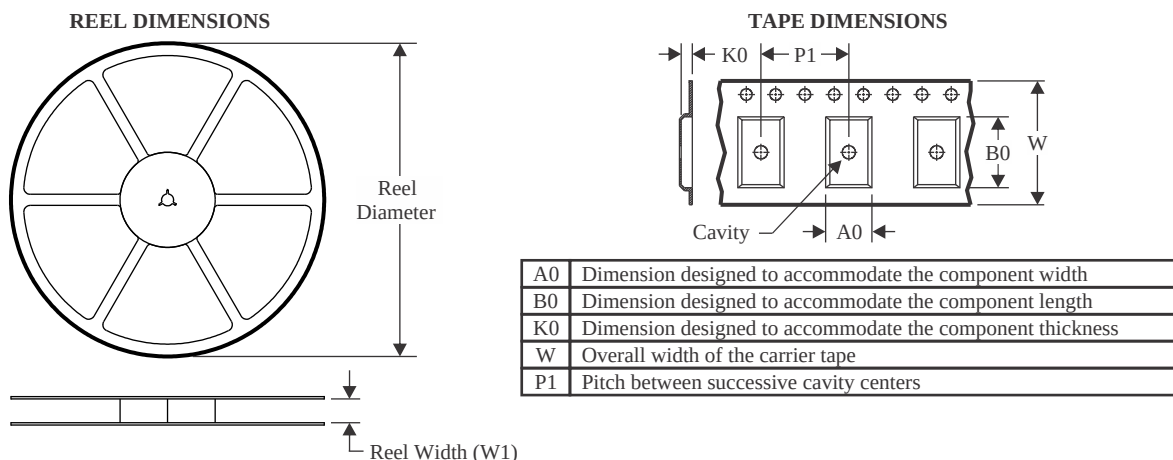
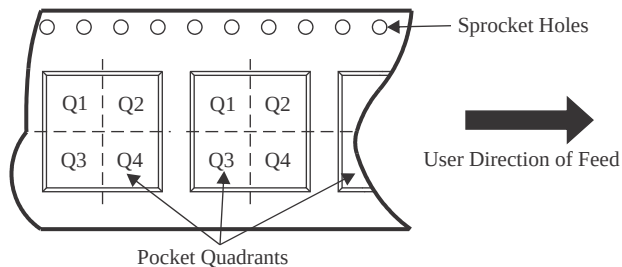



**TAPE AND REEL INFORMATION**

**QUADRANT ASSIGNMENTS FOR PIN 1 ORIENTATION IN TAPE**


\*All dimensions are nominal

| Device        | Package Type | Package Drawing | Pins | SPQ  | Reel Diameter (mm) | Reel Width W1 (mm) | A0 (mm) | B0 (mm) | K0 (mm) | P1 (mm) | W (mm) | Pin1 Quadrant |
|---------------|--------------|-----------------|------|------|--------------------|--------------------|---------|---------|---------|---------|--------|---------------|
| TPS62230DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62230DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622310DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622310DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622311DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622311DRYT | SON          | DRY             | 6    | 250  | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622312DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622312DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622313DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622313DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622314DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622314DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622314DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622314DRYT | SON          | DRY             | 6    | 250  | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622315DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622315DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |

| Device        | Package Type | Package Drawing | Pins | SPQ  | Reel Diameter (mm) | Reel Width W1 (mm) | A0 (mm) | B0 (mm) | K0 (mm) | P1 (mm) | W (mm) | Pin1 Quadrant |
|---------------|--------------|-----------------|------|------|--------------------|--------------------|---------|---------|---------|---------|--------|---------------|
| TPS622316DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622316DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622317DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622317DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622318DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622318DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622319DRYR | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS622319DRYT | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62231DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62231DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62231DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62231DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62232DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62232DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62233DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62233DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62234DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62234DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62235DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62235DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62236DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62236DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62237DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62237DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 9.5                | 1.2     | 1.65    | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62237DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62238DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62238DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62239DRYR  | SON          | DRY             | 6    | 5000 | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
| TPS62239DRYT  | SON          | DRY             | 6    | 250  | 180.0              | 8.4                | 1.25    | 1.6     | 0.7     | 4.0     | 8.0    | Q1            |
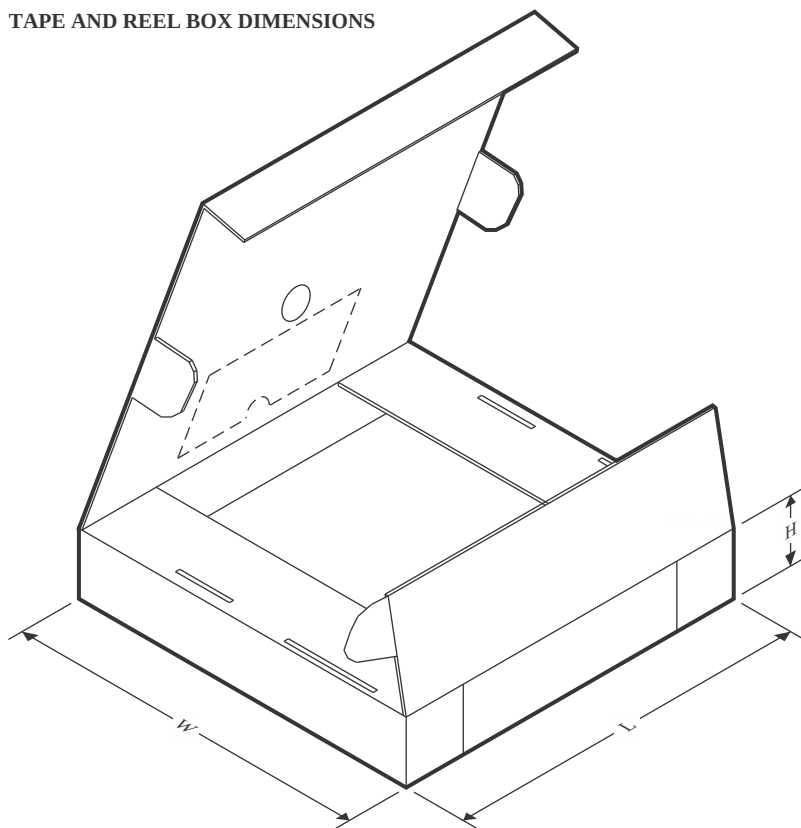
## TAPE AND REEL BOX DIMENSIONS



\*All dimensions are nominal

| Device        | Package Type | Package Drawing | Pins | SPQ  | Length (mm) | Width (mm) | Height (mm) |
|---------------|--------------|-----------------|------|------|-------------|------------|-------------|
| TPS62230DRYR  | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS62230DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS622310DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622310DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS622311DRYR | SON          | DRY             | 6    | 5000 | 189.0       | 185.0      | 36.0        |
| TPS622311DRYT | SON          | DRY             | 6    | 250  | 189.0       | 185.0      | 36.0        |
| TPS622312DRYR | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS622312DRYT | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS622313DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622313DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS622314DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622314DRYT | SON          | DRY             | 6    | 5000 | 189.0       | 185.0      | 36.0        |
| TPS622314DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS622314DRYT | SON          | DRY             | 6    | 250  | 189.0       | 185.0      | 36.0        |
| TPS622315DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622315DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS622316DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622316DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |

| Device        | Package Type | Package Drawing | Pins | SPQ  | Length (mm) | Width (mm) | Height (mm) |
|---------------|--------------|-----------------|------|------|-------------|------------|-------------|
| TPS622317DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622317DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS622318DRYR | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS622318DRYT | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS622319DRYR | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS622319DRYT | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS62231DRYR  | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS62231DRYR  | SON          | DRY             | 6    | 5000 | 189.0       | 185.0      | 36.0        |
| TPS62231DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS62231DRYT  | SON          | DRY             | 6    | 250  | 189.0       | 185.0      | 36.0        |
| TPS62232DRYR  | SON          | DRY             | 6    | 5000 | 189.0       | 185.0      | 36.0        |
| TPS62232DRYT  | SON          | DRY             | 6    | 250  | 189.0       | 185.0      | 36.0        |
| TPS62233DRYR  | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS62233DRYT  | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS62234DRYR  | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS62234DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS62235DRYR  | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS62235DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS62236DRYR  | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS62236DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS62237DRYR  | SON          | DRY             | 6    | 5000 | 189.0       | 185.0      | 36.0        |
| TPS62237DRYT  | SON          | DRY             | 6    | 250  | 189.0       | 185.0      | 36.0        |
| TPS62237DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |
| TPS62238DRYR  | SON          | DRY             | 6    | 5000 | 202.0       | 201.0      | 28.0        |
| TPS62238DRYT  | SON          | DRY             | 6    | 250  | 202.0       | 201.0      | 28.0        |
| TPS62239DRYR  | SON          | DRY             | 6    | 5000 | 183.0       | 183.0      | 20.0        |
| TPS62239DRYT  | SON          | DRY             | 6    | 250  | 183.0       | 183.0      | 20.0        |